

ISO 9001:2008



PASTERNAK®

www.Pasternack.com

Cable Assembly Identifier Section Catalog 2011A

Pasternack Enterprises, Inc.
P.O. Box 16759
Irvine, CA 92623
Toll-Free: (866) 727-8376
Direct: (949) 261-1920
Fax: (949) 261-7451

*Over 20,000 RF, Microwave & Fiber Optics products
available for same-day shipping.*













© Copyright 2011 Pasternack Enterprises, Inc.
All Rights Reserved. Printed in U.S.A.



CONNECTOR IDENTIFIER

DIMENSIONS ARE IN INCHES, UNLESS NOTED OTHERWISE

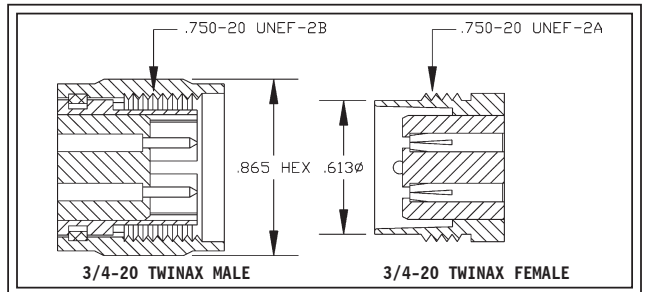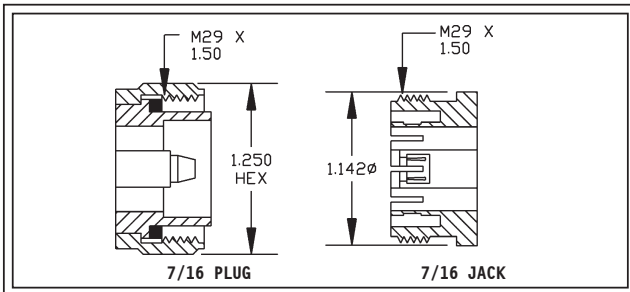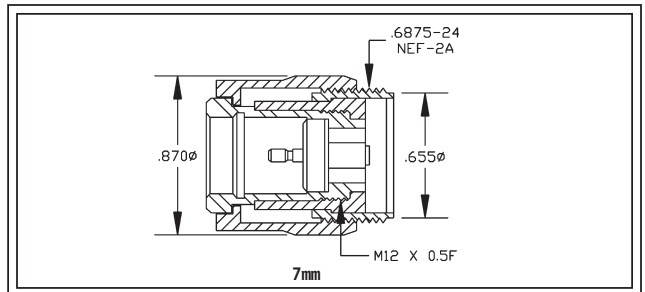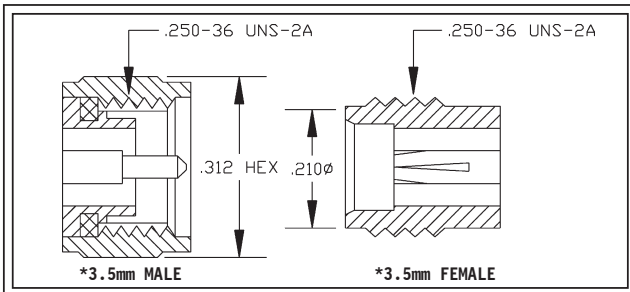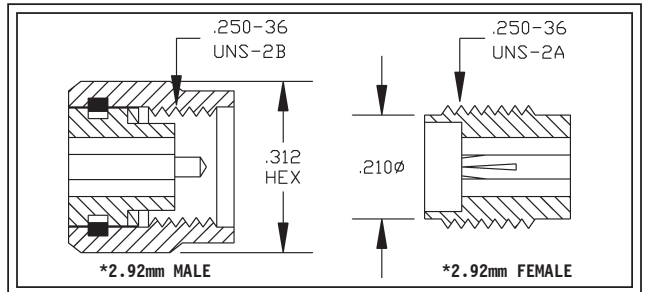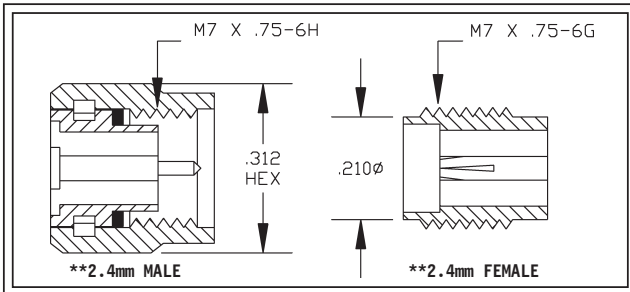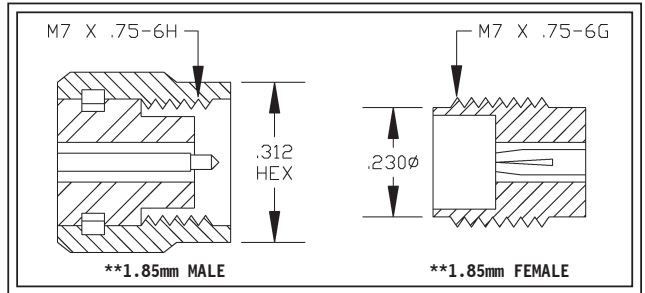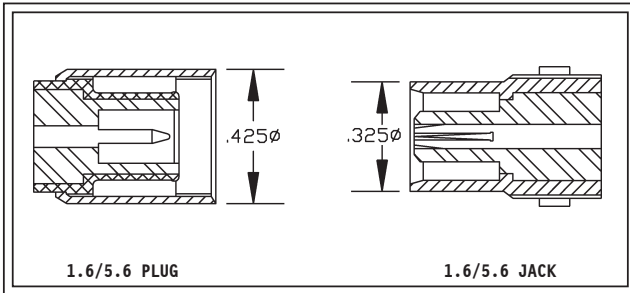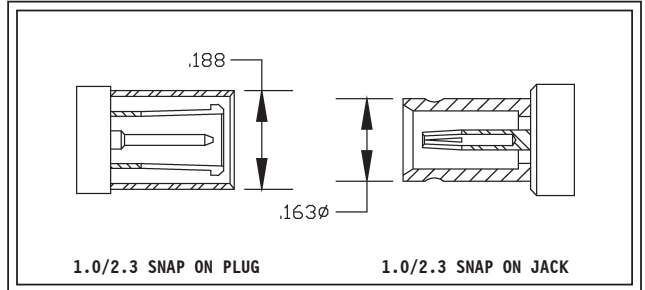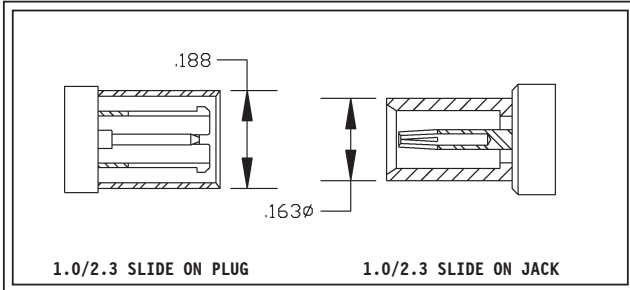

*SMA, 2.92mm, 3.5mm & K CONNECTORS WILL MATE MECHANICALLY & ELECTRICALLY TO EACH OTHER. THE K CONNECTOR IS A TRADEMARK OF THE ANRITSU COMPANY.
****1.85mm, 2.4mm & V CONNECTORS WILL MATE MECHANICALLY & ELECTRICALLY TO EACH OTHER. THE V CONNECTOR IS A TRADEMARK OF THE ANRITSU COMPANY.**

SPECIFICATIONS SHOWN ARE INTENDED FOR IDENTIFICATION PURPOSES ONLY











Free Ground Freight
 Same-Day Shipping

All Products Available Online! www.pasternack.com

Toll-Free: 866-PASTERNAK (866-727-8376) Phone: 949-261-1920 Fax: 949-261-7451

CONNECTOR IDENTIFIER











DIMENSIONS ARE IN INCHES, UNLESS NOTED OTHERWISE

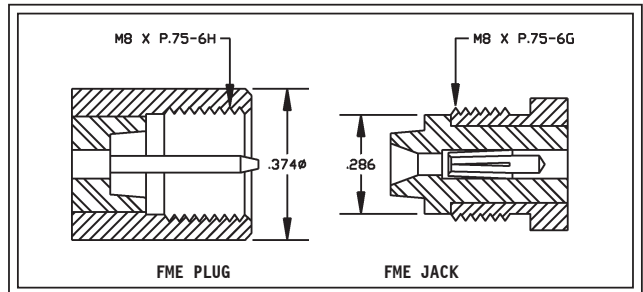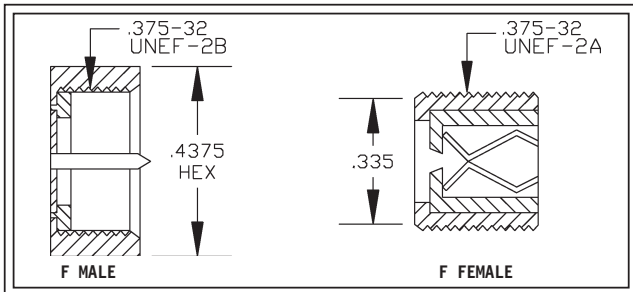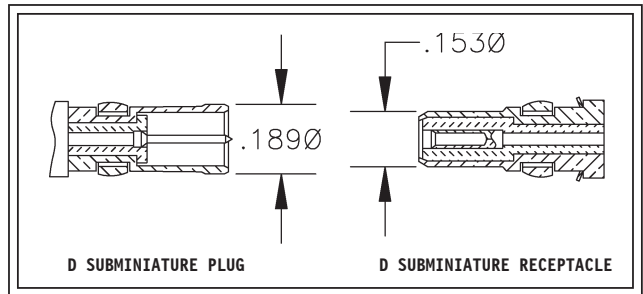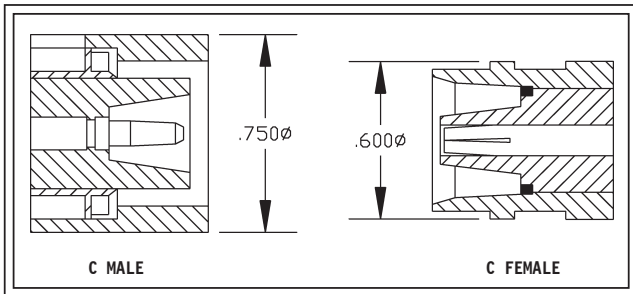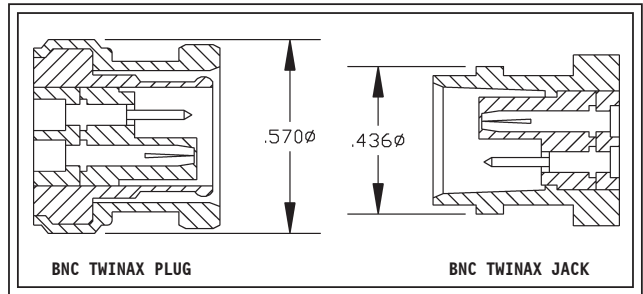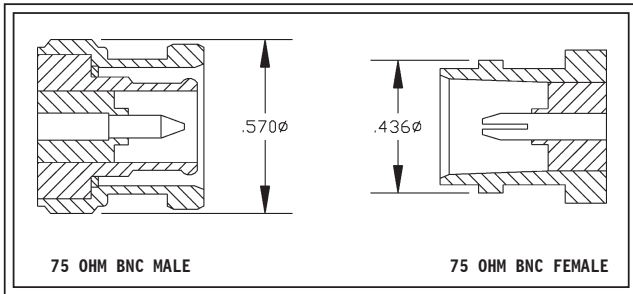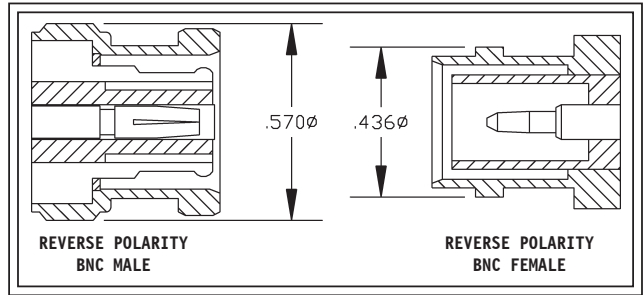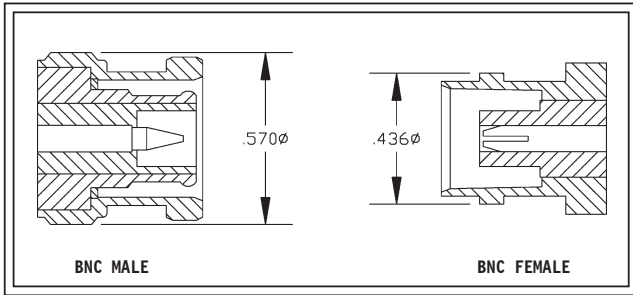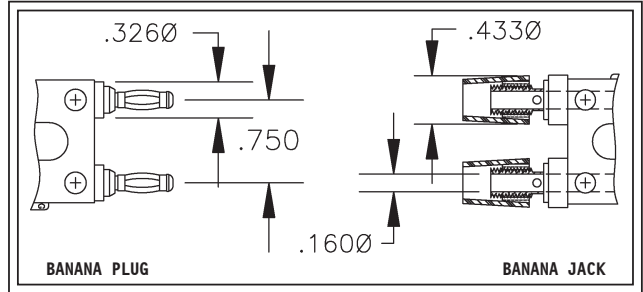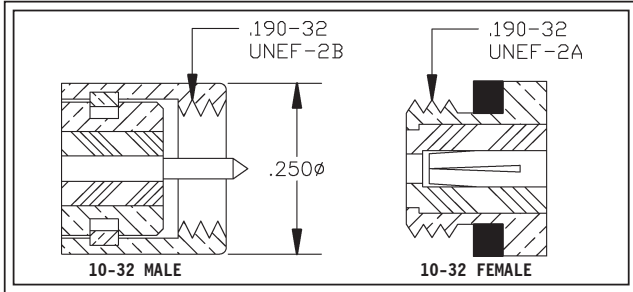

SPECIFICATIONS SHOWN ARE INTENDED FOR IDENTIFICATION PURPOSES ONLY

CONNECTOR IDENTIFIER











DIMENSIONS ARE IN INCHES, UNLESS NOTED OTHERWISE

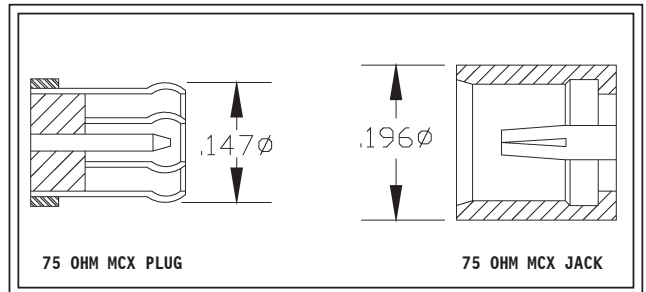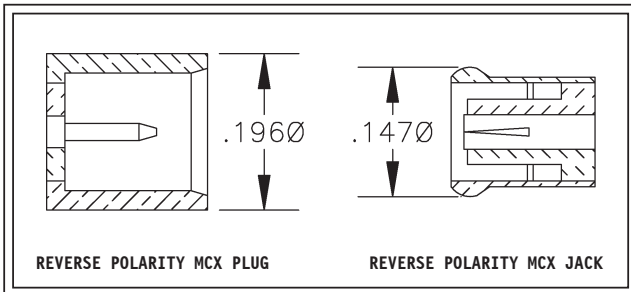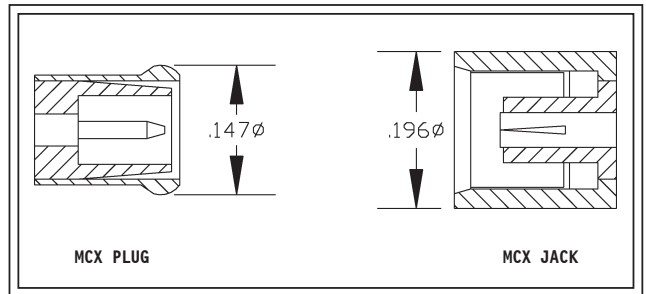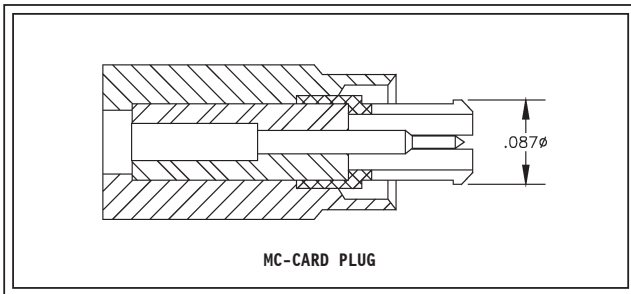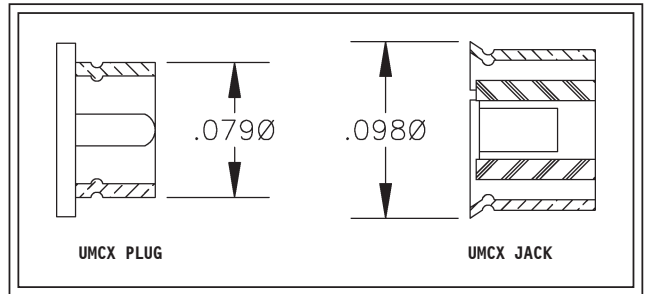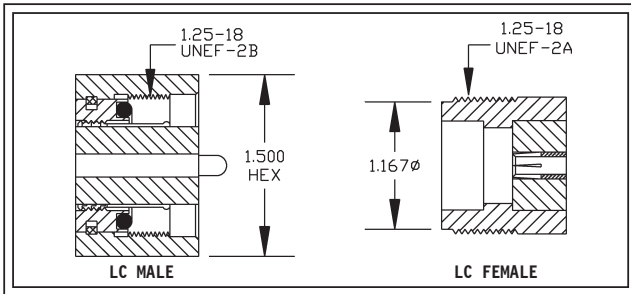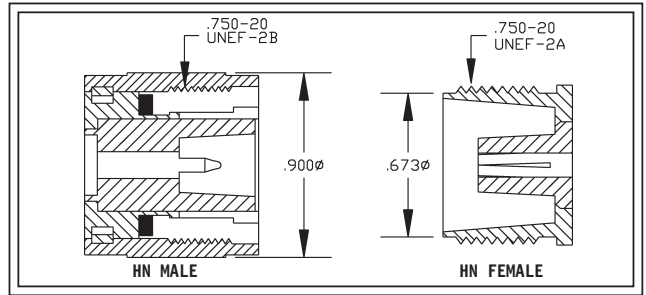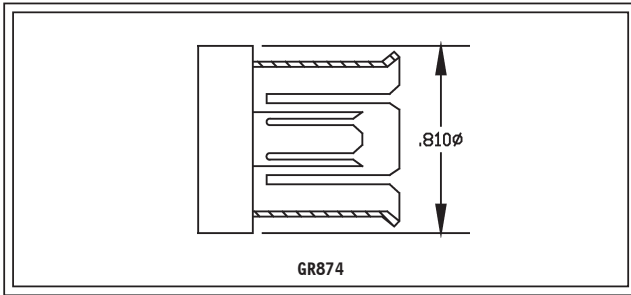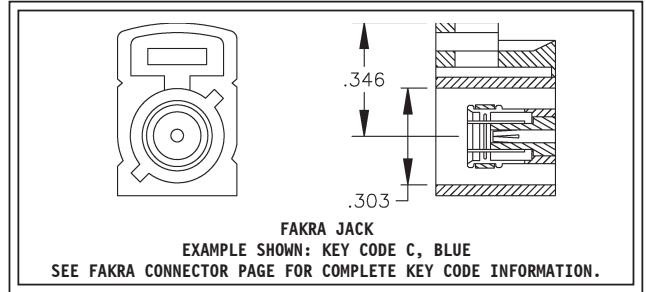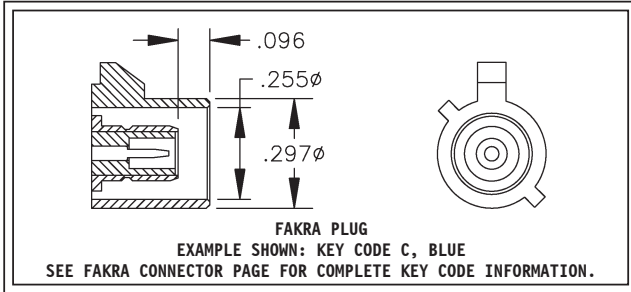

SPECIFICATIONS SHOWN ARE INTENDED FOR IDENTIFICATION PURPOSES ONLY

CONNECTOR IDENTIFIER











DIMENSIONS ARE IN INCHES, UNLESS NOTED OTHERWISE

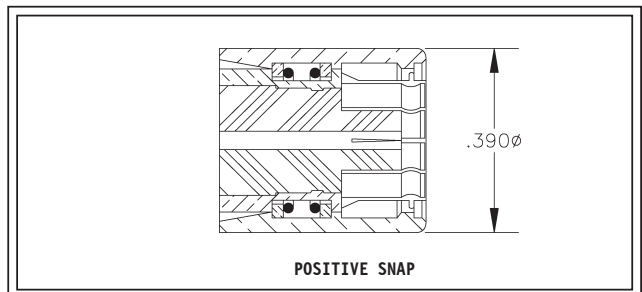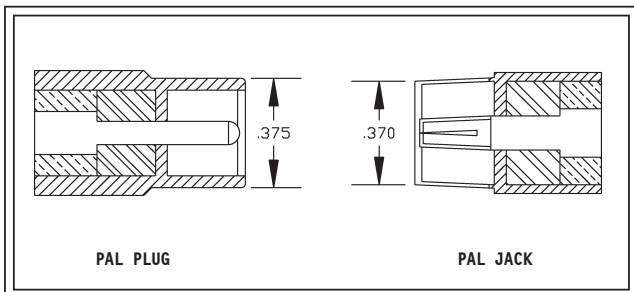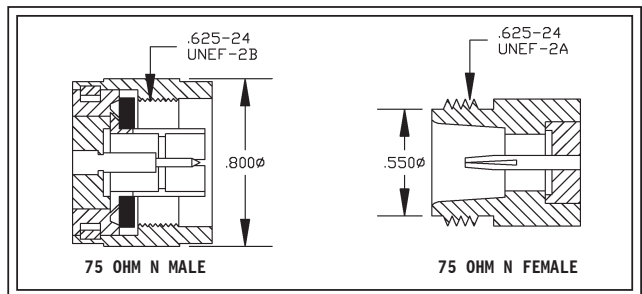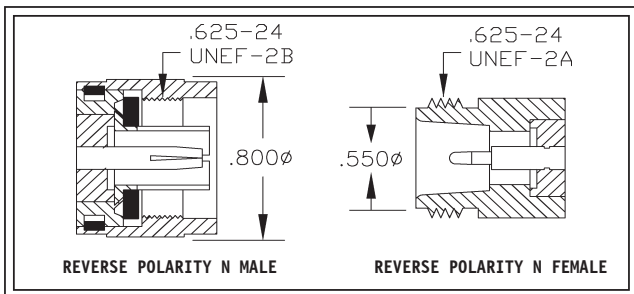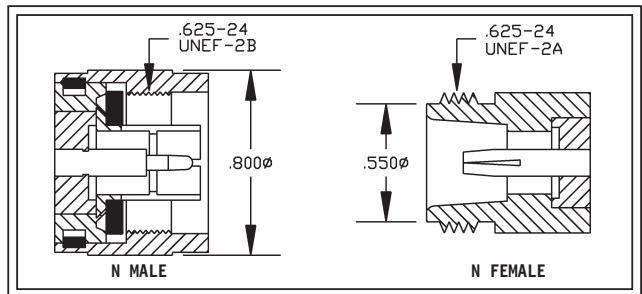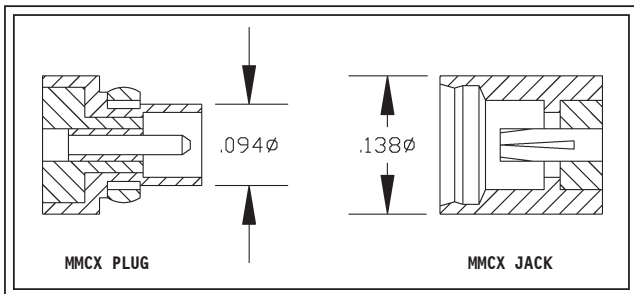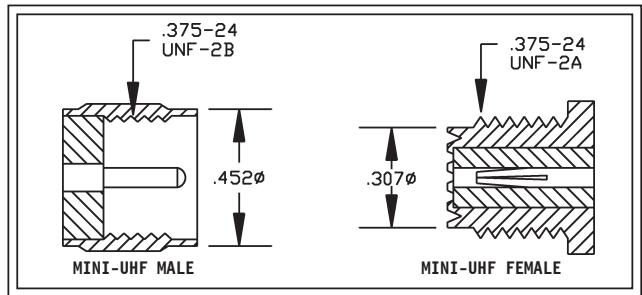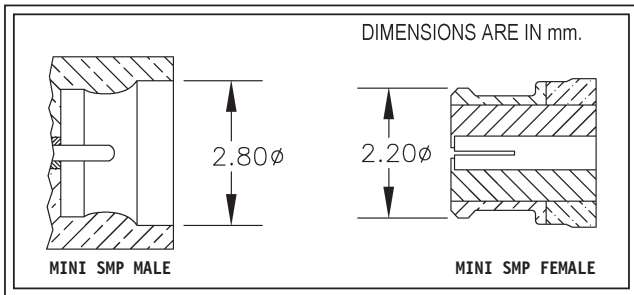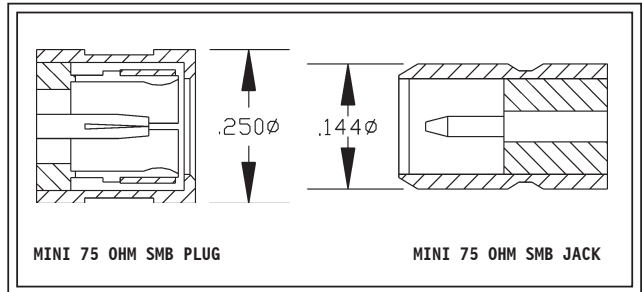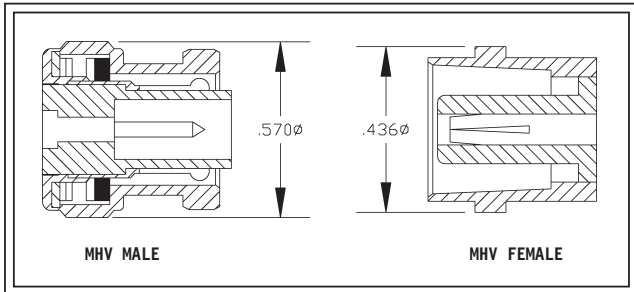

SPECIFICATIONS SHOWN ARE INTENDED FOR IDENTIFICATION PURPOSES ONLY

CONNECTOR IDENTIFIER

DIMENSIONS ARE IN INCHES, UNLESS NOTED OTHERWISE

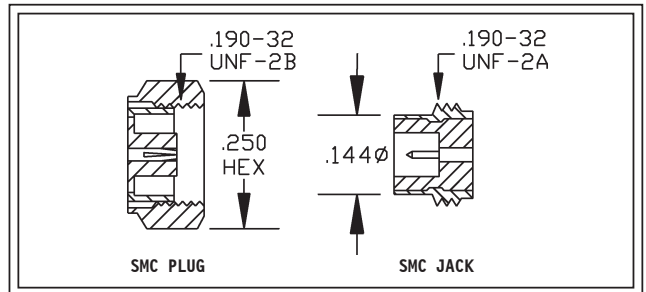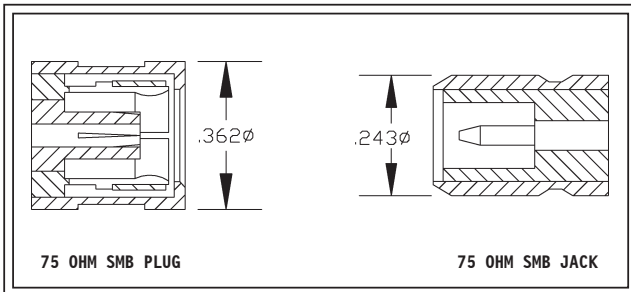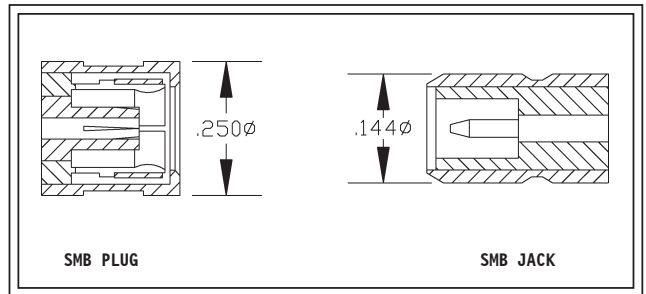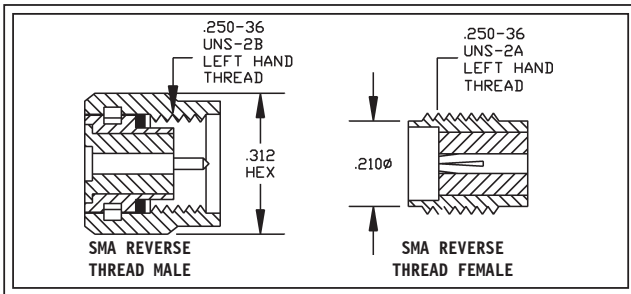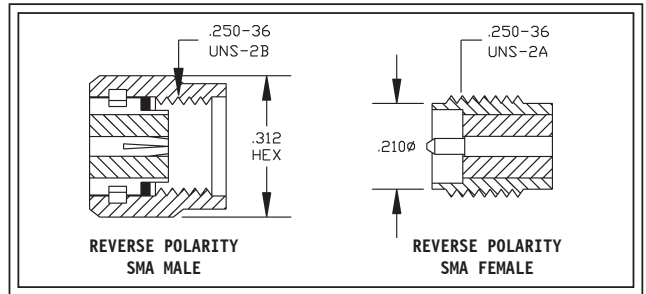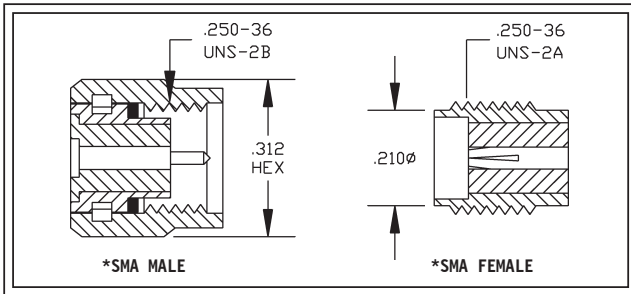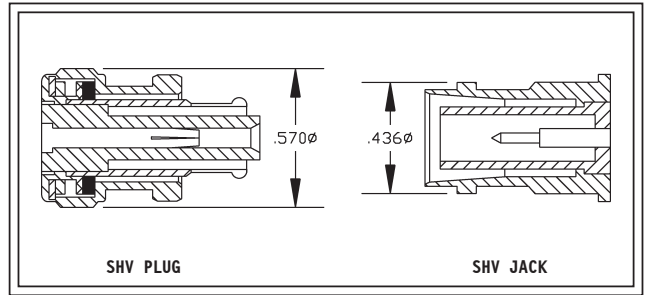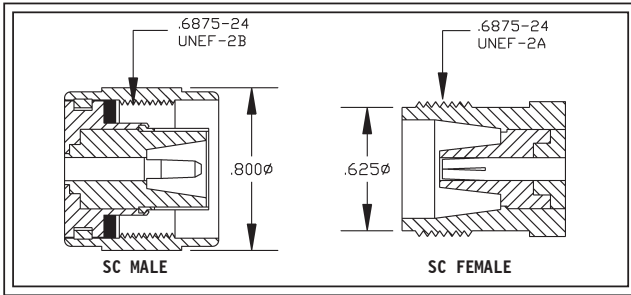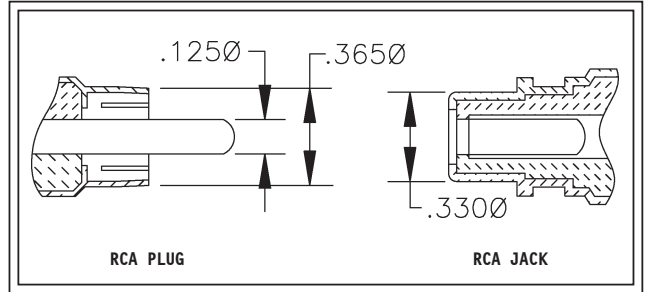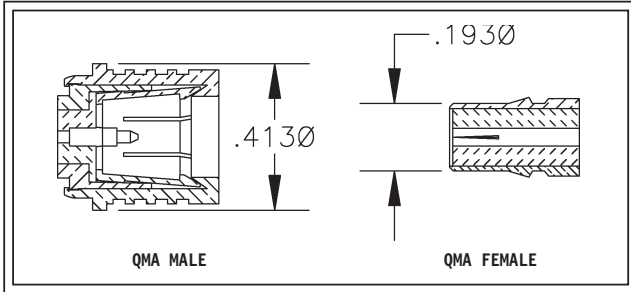

*SMA, 2.92mm, 3.5mm & K CONNECTORS WILL MATE MECHANICALLY & ELECTRICALLY TO EACH OTHER. THE K CONNECTOR IS A TRADEMARK OF THE ANRITSU COMPANY.

SPECIFICATIONS SHOWN ARE INTENDED FOR IDENTIFICATION PURPOSES ONLY









Free Ground Freight
Same-Day Shipping

All Products Available Online! www.pasternack.com

Toll-Free: 866-PASTERNAK (866-727-8376) Phone: 949-261-1920 Fax: 949-261-7451

CONNECTOR IDENTIFIER

DIMENSIONS ARE IN INCHES, UNLESS NOTED OTHERWISE

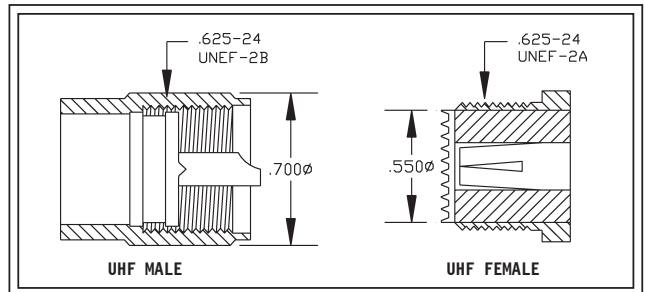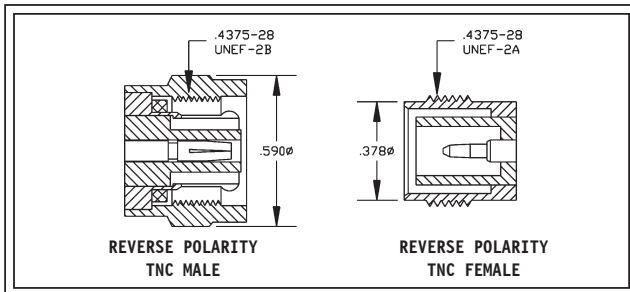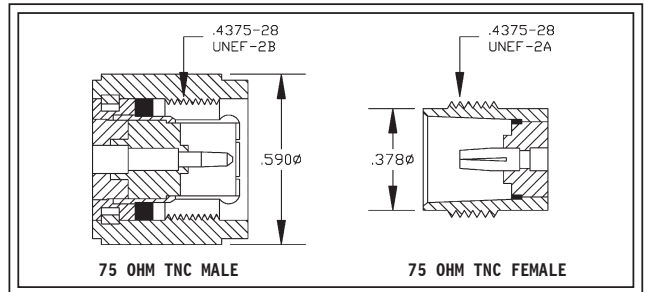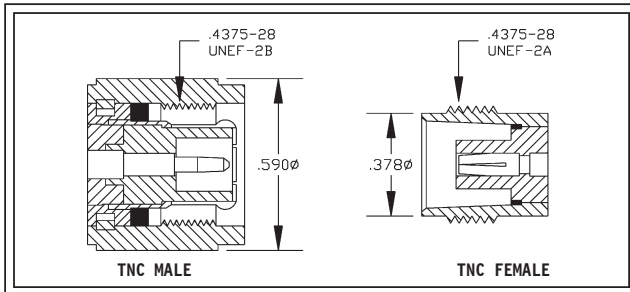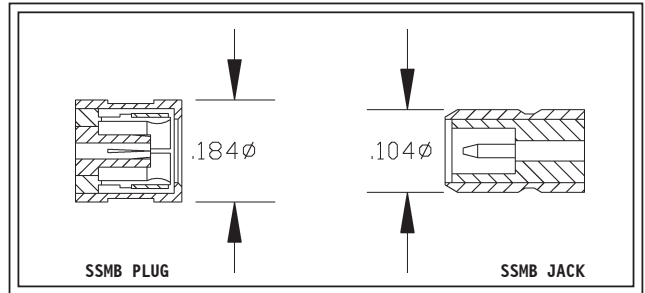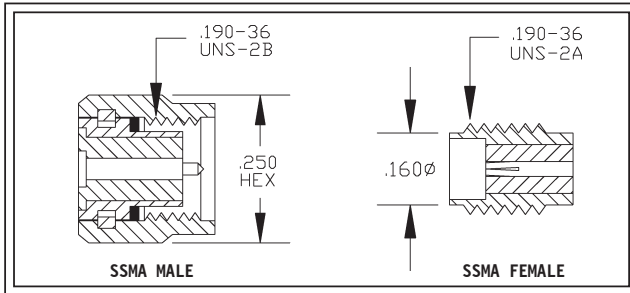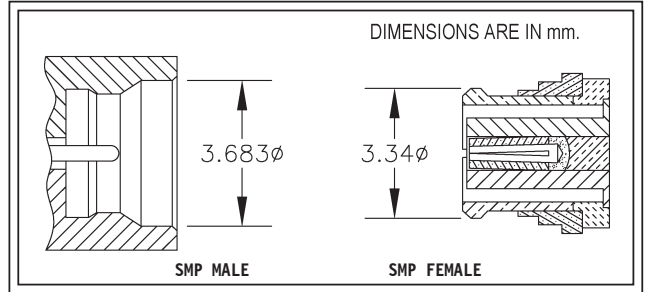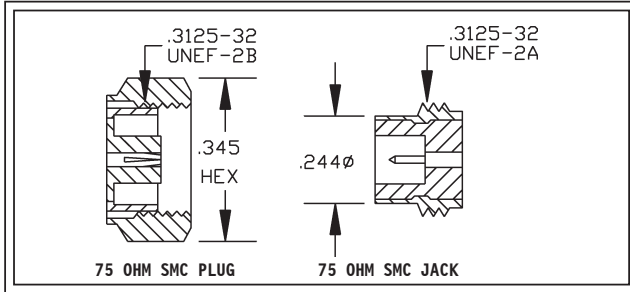

SPECIFICATIONS SHOWN ARE INTENDED FOR IDENTIFICATION PURPOSES ONLY

COAXIAL CABLE ASSEMBLY SELECTION LIST

Cable Assemblies

1.6/5.6 PLUG TO:

1.6/5.6 PLUG	108
75 OHM BNC MALE	104

1.85mm MALE TO:

1.85mm MALE	31,56
2.4mm MALE	31
2.92mm MALE	31,55

2.4mm FEMALE TO:

2.4mm MALE	56
------------------	----

2.4mm MALE TO:

1.85mm MALE	31
2.4mm FEMALE	56
2.4mm MALE	31,56
2.92mm MALE	31,55
SMA MALE	42

2.92mm FEMALE BULKHEAD TO:

2.92mm MALE	55
-------------------	----

2.92mm MALE TO:

1.85mm MALE	31,55
2.4mm MALE	31,55
2.92mm FEMALE	25
2.92mm FEMALE BULKHEAD	55
2.92mm MALE	25,31,55

2.92mm FEMALE TO:

2.92mm MALE	25
-------------------	----

3.5mm FEMALE BULKHEAD TO:

3.5mm MALE	54
------------------	----

3.5mm FEMALE TO:

3.5mm MALE	24,54
------------------	-------

3.5mm MALE TO:

3.5mm FEMALE	24,54
3.5mm FEMALE BULKHEAD	54
3.5mm MALE	24,54

3/4"-20 TWINAXIAL MALE TO:

3/4"-20 TWINAXIAL MALE	108
------------------------------	-----

7/16 DIN FEMALE TO:

7/16 DIN MALE	69
---------------------	----

7/16 DIN MALE RIGHT ANGLE TO:

7/16 DIN MALE	69
---------------------	----

7/16 DIN MALE TO:

7/16 DIN FEMALE	69
7/16 DIN MALE	68,69
7/16 DIN MALE RIGHT ANGLE	69
N MALE	61,62
SMA MALE	45

10-32 MALE RIGHT ANGLE TO:

10-32 MALE	74
10-32 MALE RIGHT ANGLE	74

10-32 MALE TO:

10-32 MALE	74
10-32 MALE RIGHT ANGLE	74
BNC MALE	74

75 OHM BNC FEMALE BULKHEAD TO:

75 OHM BNC MALE	103
-----------------------	-----

75 OHM BNC FEMALE TO:

75 OHM BNC FEMALE	105
75 OHM BNC MALE	102

75 OHM BNC MALE RIGHT ANGLE TO:

75 OHM BNC MALE	102
75 OHM BNC MALE RIGHT ANGLE	105

75 OHM BNC MALE TO:

1.6/5.6 PLUG	104
75 OHM BNC FEMALE	102
75 OHM BNC FEMALE BULKHEAD	103
75 OHM BNC MALE	102
75 OHM BNC MALE RIGHT ANGLE	102
75 OHM N MALE	104
75 OHM SMB PLUG	103
75 OHM SMC PLUG	104
75 OHM TNC MALE	104
F MALE	103
MINI 75 OHM SMB PLUG	103

75 OHM N MALE TO:

75 OHM BNC MALE	104
75 OHM N MALE	107

75 OHM SMB PLUG TO:

75 OHM BNC MALE	103
75 OHM SMB PLUG	106

75 OHM SMC PLUG TO:

75 OHM BNC MALE	104
75 OHM SMC PLUG	108

75 OHM TNC MALE TO:

75 OHM BNC MALE	104
75 OHM TNC MALE	108

ALLIGATOR CLIPS TO:

BANANA PLUG	109
BNC MALE	80

BANANA PLUG TO:

ALLIGATOR CLIPS	109
BANANA PLUG	109
BNC MALE	80

BNC FEMALE BULKHEAD TO:

BNC MALE	78,79
----------------	-------

BNC FEMALE TO:

BNC FEMALE	82,83
BNC MALE	78

BNC MALE RIGHT ANGLE TO:

BNC MALE	77
BNC MALE RIGHT ANGLE	82

BNC MALE TO:

10-32 MALE	74
ALLIGATOR CLIPS	80
BANANA PLUG	80
BNC FEMALE	78
BNC FEMALE BULKHEAD	78,79
BNC MALE	76,77
BNC MALE RIGHT ANGLE	77
FME JACK	71
FME PLUG	71
GR874	80
MINIATURE ALLIGATOR CLIPS	81
MINIATURE STACKING BANANA PLUGS	81
N MALE	62,63
REVERSE POLARITY SMA MALE	79
REVERSE POLARITY TNC MALE	80
SAFETY HOOKS	81
SMA MALE	46,47
SMA MALE RIGHT ANGLE	51
SMB PLUG	79
SMC PLUG	73
STACKING TIP PLUGS	81
STANDARD STACKING BANANA PLUGS	81
TNC MALE	67,68
UHF MALE	70
UNTERMINATED WIRES	81

BNC TWINAX MALE TO:

BNC TWINAX MALE	108
-----------------------	-----

C MALE TO:

C MALE	101
--------------	-----

F FEMALE BULKHEAD TO:

F MALE	106
--------------	-----

F MALE RIGHT ANGLE TO:

F MALE	105
--------------	-----

F MALE TO:

75 OHM BNC MALE	103
F FEMALE BULKHEAD	106
F MALE	105
F MALE RIGHT ANGLE	105

FAKRA JACK TO:

FAKRA PLUG	93,94
FAKRA JACK	94,95
SMA FEMALE	100,101
SMA MALE	99,100

FAKRA JACK RIGHT ANGLE TO:

FAKRA PLUG	95,96
------------------	-------

FAKRA PLUG TO:

FAKRA PLUG	92,93
FAKRA JACK	93,94
FAKRA JACK RIGHT ANGLE	95,96
SMA FEMALE	97,98
SMA MALE	96,97

FME JACK BULKHEAD TO:

UMCX PLUG	87
-----------------	----

FME JACK BULKHEAD, REAR MOUNT TO:

UMCX PLUG	87
-----------------	----

FME JACK TO:

BNC MALE	71
FME JACK	71

FME PLUG TO:

BNC MALE	71
FME PLUG	71

GR874 TO:

BNC MALE	80
GR874	109

HN MALE TO:

HN MALE	75
---------------	----

LC MALE TO:

LC MALE	75
---------------	----

MC-CARD PLUG TO:

SMA MALE	48
----------------	----

MCX JACK BULKHEAD TO:

UMCX PLUG	86
-----------------	----

MCX PLUG RIGHT ANGLE TO:

MCX PLUG	88
MCX PLUG RIGHT ANGLE	89
UMCX PLUG	86

MCX PLUG TO:

MCX PLUG	88
MCX PLUG RIGHT ANGLE	88
UMCX PLUG	86

MHV MALE TO:

MHV MALE	83
SHV PLUG	83

MINI 75 OHM SMB JACK TO:

MINI 75 OHM SMB PLUG	107
----------------------------	-----

MINI 75 OHM SMB PLUG RIGHT ANGLE TO:

MINI 75 OHM SMB PLUG	107
MINI 75 OHM SMB PLUG RIGHT ANGLE	107

MINI 75 OHM SMB PLUG TO:

75 OHM BNC MALE	103
MINI 75 OHM SMB JACK	107
MINI 75 OHM SMB PLUG	106
MINI 75 OHM SMB PLUG RT ANGLE	107

MINI UHF MALE TO:

MINI UHF MALE	71
N MALE	62
SMA MALE	46

MINIATURE ALLIGATOR CLIPS TO:

BNC MALE	81
----------------	----

ROHS COMPLIANT & CUSTOM-LENGTH CABLE ASSEMBLIES MAY BE ORDERED ON OUR WEBSITE.

COAXIAL CABLE ASSEMBLY SELECTION LIST (CONT'D)

MINIATURE STACKING BANANA PLUGS TO:	
BNC MALE	81
MMCX PLUG RIGHT ANGLE TO:	
MMCX PLUG	88
UMCX PLUG	86
MMCX PLUG TO:	
MMCX PLUG	88
MMCX PLUG RIGHT ANGLE	88
SMA MALE	47
N FEMALE BULKHEAD TO:	
N MALE	27,29,60
N MALE RIGHT ANGLE	65
SMA MALE	27,29,44
N FEMALE TO:	
N MALE	59,60
QN MALE	65,66
QN MALE RIGHT ANGLE	66
N MALE RIGHT ANGLE TO:	
N FEMALE BULKHEAD	65
N MALE	23,58,59
N MALE RIGHT ANGLE	64,65
N MALE TO:	
7/16 DIN MALE	61,62
BNC MALE	62,63
MINI UHF MALE	62
N FEMALE	59,60
N FEMALE BULKHEAD	27,29,60
N MALE	23,27,29,57,58
N MALE RIGHT ANGLE	23,58,59
QN MALE	63
QN MALE RIGHT ANGLE	63
REVERSE POLARITY SMA MALE	63,64
REVERSE POLARITY TNC MALE	64
SMA FEMALE	23
SMA MALE	23,27,29,42,43
TNC MALE	61
UMCX PLUG	87
QMA MALE TO:	
QMA MALE	84
SMA FEMALE	52
SMA MALE	47
QN MALE TO:	
N FEMALE	65,66
N MALE	63
QN MALE	84
QN MALE RIGHT ANGLE	85
QN MALE RIGHT ANGLE TO:	
N FEMALE	66
N MALE	63
QN MALE	85
REVERSE POLARITY MCX JACK BULKHEAD TO:	
UMCX PLUG	87
REVERSE POLARITY SMA FEMALE BULKHEAD TO:	
UMCX PLUG	87
REVERSE POLARITY SMA MALE TO:	
BNC MALE	79
N MALE	63,64
SMA MALE	48,49
TNC MALE	68
REVERSE POLARITY TNC FEMALE BULKHEAD TO:	
UMCX PLUG	87
REVERSE POLARITY TNC MALE TO:	
BNC MALE	80
N MALE	64
SMA MALE	49
TNC MALE	68
REVERSE THREAD SMA FEMALE BULKHEAD TO:	
UMCX PLUG	87
REVERSE THREAD SMA MALE TO:	
REVERSE THREAD SMA MALE	108
SMA MALE	49
RCA FEMALE BULKHEAD TO:	
RCA MALE	106

RCA MALE RIGHT ANGLE TO:	
RCA MALE	106
RCA MALE TO:	
RCA FEMALE BULKHEAD	106
RCA MALE	106
RCA MALE RIGHT ANGLE	106
SAFETY HOOKS TO:	
BNC MALE	81
SC MALE TO:	
SC MALE	74,75
SHV PLUG TO:	
MHV MALE	83
SHV PLUG	84
SMA FEMALE 2 HOLE PANEL MOUNT TO:	
SMA FEMALE 2 HOLE PANEL MOUNT	53
SMA FEMALE 4 HOLE PANEL MOUNT TO:	
SMA FEMALE 4 HOLE PANEL MOUNT	54
SMA FEMALE BULKHEAD TO:	
UMCX PLUG	86
SMA FEMALE BULKHEAD	53
SMA MALE	27,41,42
SMA MALE RIGHT ANGLE	27,50,51
SMA FEMALE TO:	
FAKRA JACK	100,101
FAKRA PLUG	97,98
N MALE	23
QMA MALE	52
SMA FEMALE	51,52
SMA MALE	40,41
SMA MALE RIGHT ANGLE TO:	
BNC MALE	51
SMA FEMALE BULKHEAD	27,50
SMA MALE	23,27,29,39,40
SMA MALE RIGHT ANGLE	27,29,49,50
SMA MALE TO:	
2.4mm MALE	42
7/16 DIN MALE	45
BNC MALE	46,47
FAKRA JACK	99,100
FAKRA PLUG	96,97
MC-CARD PLUG	48
MINI UHF MALE	46
MMCX PLUG	47
N FEMALE BULKHEAD	27,29,44
N MALE	23,27,29,42,43
QMA MALE	47
REVERSE POLARITY SMA MALE	48,49
REVERSE POLARITY TNC MALE	49
REVERSE THREAD SMA MALE	49
SMA FEMALE	40,41
SMA FEMALE BULKHEAD	27,41,42
SMA MALE	23,27,29,38,39
SMA MALE, PUSH ON	23
SMA MALE, QUICK DISCONNECT	23
SMA MALE RIGHT ANGLE	23,27,29,39,40
SMB PLUG	48
SMC PLUG	46
SMP FEMALE	47
SSMA MALE	42
TNC MALE	23,27,44,45
TNC MALE RIGHT ANGLE	23
UMCX PLUG	86
SMB JACK BULKHEAD TO:	
SMB PLUG	90
SMB PLUG RIGHT ANGLE	91
SMB PLUG RIGHT ANGLE TO:	
SMB JACK BULKHEAD	91
SMB PLUG	89,90
SMB PLUG RIGHT ANGLE	90,91
SMB PLUG TO:	
BNC MALE	79
SMA MALE	48
SMB JACK BULKHEAD	90
SMB PLUG	89
SMB PLUG RIGHT ANGLE	89,90


SMC JACK BULKHEAD TO:	
SMC PLUG	72
SMC PLUG RIGHT ANGLE	73
UMCX PLUG	87
SMC PLUG RIGHT ANGLE TO:	
SMC JACK BULKHEAD	73
SMC PLUG	72
SMC PLUG RIGHT ANGLE	73
SMC PLUG TO:	
BNC MALE	73
SMA MALE	46
SMC JACK BULKHEAD	72
SMC PLUG	71,72
SMC PLUG RIGHT ANGLE	72
SMP FEMALE RIGHT ANGLE TO:	
SMP FEMALE	85
SMP FEMALE TO:	
SMA MALE	47
SMP FEMALE	85
SMP FEMALE RIGHT ANGLE	85
SSMA MALE TO:	
SMA MALE	42
SSMA MALE	56
SSMB PLUG RIGHT ANGLE TO:	
SSMB PLUG RIGHT ANGLE	101
SSMB PLUG TO:	
UMCX PLUG	87
STACKING TIP PLUGS TO:	
BNC MALE	81
STANDARD STACKING BANANA PLUGS TO:	
BNC MALE	81
TNC FEMALE BULKHEAD TO:	
UMCX PLUG	87
TNC MALE RIGHT ANGLE TO:	
SMA MALE	23
TNC MALE TO:	
BNC MALE	67,68
N MALE	61
REVERSE POLARITY SMA MALE	68
REVERSE POLARITY TNC MALE	68
SMA MALE	23,27,44,45
TNC MALE	27,66,67
UHF MALE TO:	
BNC MALE	70
UHF MALE	69,70
UMCX PLUG TO:	
FME JACK BULKHEAD	87
FME JACK BULKHEAD, REAR MOUNT	87
MCX JACK BULKHEAD	86
MCX PLUG	86
MCX PLUG RIGHT ANGLE	86
MMCX PLUG RIGHT ANGLE	86
N MALE	87
PIGTAIL	86
REV. POLARITY MCX JACK BULKHEAD	87
REV. POLARITY SMA FEMALE BULKHEAD	87
REV. POLARITY TNC FEMALE BULKHEAD	87
REV. THREAD SMA FEMALE BULKHEAD	87
SMA FEMALE BULKHEAD	86
SMA MALE	86
SMC JACK BULKHEAD	87
SSMB PLUG	87
TNC FEMALE BULKHEAD	87
UMCX PLUG	86
UNTERMINATED WIRES TO:	
BNC MALE	81
BREAKOUTS	
SINGLE WIRE PATCH CORD	
110	
110	

Cable Assemblies

ROHS COMPLIANT & CUSTOM-LENGTH CABLE ASSEMBLIES MAY BE ORDERED ON OUR WEBSITE.

CONNECTOR FREQUENCY RANGE CHART

Cable Assemblies

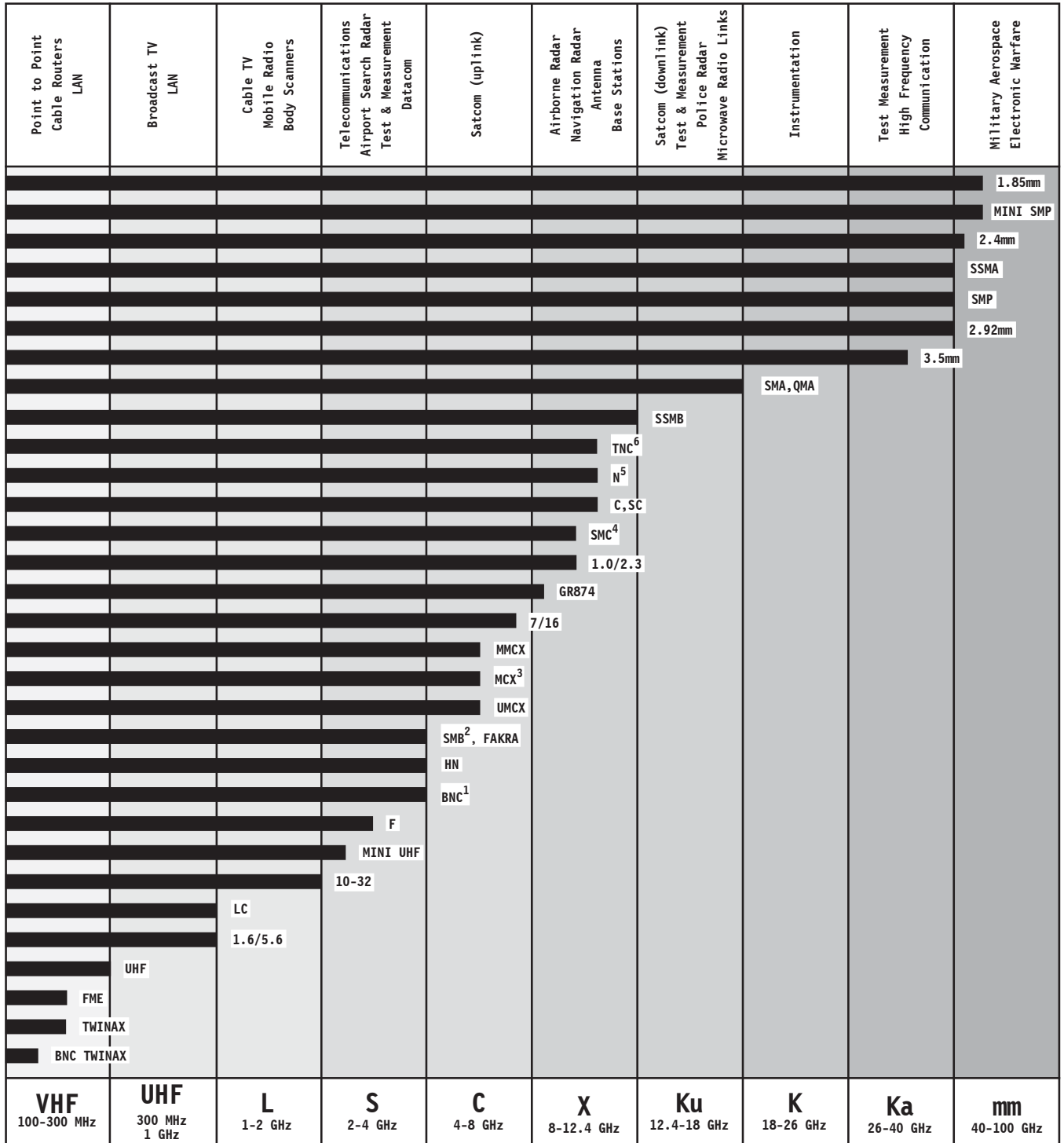

Notes:

- 1: BNC-75 Ohm connectors operate up to 1 GHz
- 2: SMB-75 Ohm & Mini SMB-75 Ohm connectors operate up to 4 GHz
- 3: MCX-75 Ohm connectors operate up to 6 GHz
- 4: SMC-75 Ohm connectors operate up to 10 GHz
- 5: N-75 Ohm connectors operate up to 1.5 GHz
- 6: TNC-75 Ohm connectors operate up to 1 GHz

ROHS COMPLIANT & CUSTOM-LENGTH CABLE ASSEMBLIES MAY BE ORDERED ON OUR WEBSITE.